


Test Adaptor for VMEbus

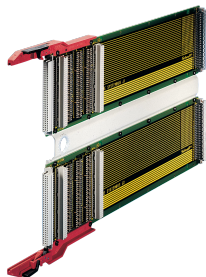

Test Adaptor for VMEbus Boards to access test points on the board.

CERTIFICATIONS



FEATURES

Routing and layer stack-up match the requirements of the VME bus

Measuring field for current and voltage measurement (V/I), (a)

Additional measuring pins, e.g. for the probe tips of an oscilloscope (b)

1 pin position for second test object, 1 pin position for terminator board

6 U test adaptors consist of two 3 U test adaptors linked via an intermediate adaptor

Voltage supply lines are designed for 2 A

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23022-002	VMEbus	C96, System Bus, C96, I/O Bus	160mm	6U	Current, Voltage	6
23021-002	VMEbus	C96, System Bus	220mm	3U	Current, Voltage	6

CatalogNumber	Type	ConnectorType	Board Depth	Rack Height	MeasuringField	Number of Layers
23021-100	VMEbus	C96, I/O Bus	160mm	3U	Current, Voltage	6
23021-001	VMEbus	C96, System Bus	160mm	3U	Current, Voltage	6
23021-101	VMEbus	C96, I/O Bus	220mm	3U	Current, Voltage	6
23022-010	VMEbus	C96, System Bus, C96, I/O Bus	280mm	6U	Current, Voltage	6
23022-004	VMEbus	C96, System Bus, C96, I/O Bus	220mm	6U	Current, Voltage	6

Table 2/2

Catalog Number	Package Quantity	Quick Ship
23022-002	1	No
23021-002	1	No
23021-100	1	No
23021-001	1	No
23021-101	1	No
23022-010	1	No
23022-004	1	No

ADDITIONAL PRODUCT DETAILS

For 9 U VMEbus test Adapter solution see Intermediate Adaptor Adaptor Bracket, 9 U, 220 mm, 350 mm.

P1 = System Bus, P2 = I/O Bus.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE