

Branch Line Restraint Structure Attachment to Steel



CERTIFICATIONS



FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	Flange Thickness (FT)	Height (H)	Length (L)	Width (W)
CSBBRS1EG		0.375, 0.5	2.7 - 12.7 mm	28.2 mm	40.4mm	26.9 mm
CSBBRS1MEG	402239	10, 12	2.7 - 12.7 mm	28.2 mm	40.4mm	26.9 mm


Table 2/2

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Certifications
CSBBS1EG		2.7 mm	32mm	OSHPD, UL, FM Approved, Seismic
CSBBS1MEG	402239	2.7 mm	32mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

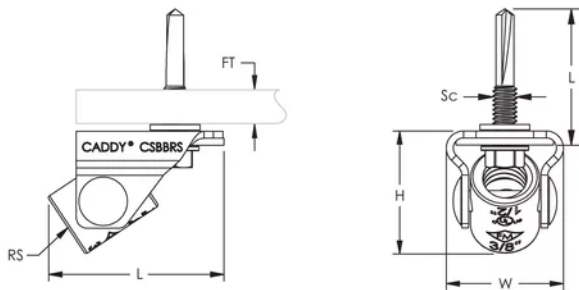

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

