

In-Line Cable Connector



CERTIFICATIONS



FEATURES

Cable splicer with four bolts for pressure on each cable

LPC513 is compatible with nVent ERICO Cu-Bond Round Conductors

SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2

Catalog Number	Material	Finish	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Width (W)	nVent ERICO Cu-Bond Conductor
LPA513	Aluminum		19.05 mm	14.3 mm	82.55 mm	
LPC513	Copper		19.05 mm	14.3 mm	82.55 mm	CBSC8, CBSC10, CBSC13
LPC513L	Copper	Tinned	19.05 mm	14.3 mm	82.55 mm	


Table 2/2

Catalog Number	Unit Weight	Complies With
LPA513	0.09 kg	
LPC513	0.17 kg	IEC® 62561-1
LPC513L	0.17 kg	

ADDITIONAL PRODUCT DETAILS

IEC compliance is valid only for nVent ERICO Cu-Bond Conductors listed.

DIAGRAMS

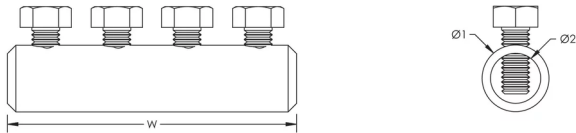

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE