


Connecting Busbar, Tinned Aluminum, 20 Connections

CATALOG NUMBER

CB20X10AL

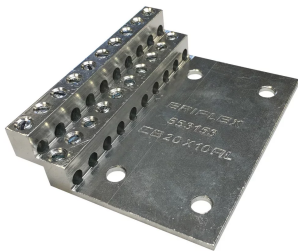

nVent ERIFLEX Connecting, Earthing and Neutral Busbars are used to connect several earthing conductors within a panel and can be used in a variety of different applications including switchgear and control equipment, electrical equipment, for wind and solar power generation and in data centers. CB Busbars can also be used to collect DC current from Solar Panel.

CERTIFICATIONS



FEATURES

Ideal for solar applications

Tinned aluminum bar allows for copper or aluminum conductor connections

Design allows for visual inspection of conductor and confirmation of connection

Can be fixed on standoff insulators or punched or threaded copper busbar

High fill ratio allows output connection with or without terminal

Quick and easy installation

RoHS compliant

PRODUCT ATTRIBUTES

Article Number: 553153

Material: Aluminum

Finish: Tinned

Max Current Rating, IEC: 640A

Number of Connections: 20

Conductor Size, IEC: (20) 1.5 - 6 mm² Stranded

Ferrule Conductor Size, IEC: (20) 2.5 - 6 mm²

Conductor Size, UL: (20) #14 - #6 Solid;(20) #16 - #6 Stranded

Depth (D): 22mm

Height (H): 72 mm

Width (W): 88 mm

Thickness (T): 2.5 mm

Hole Size 1 (HS1): 6.6 mm

A: 9.5 mm

B: 31.75 mm


C: 62.75 mm

Torque (TQ): 2 N·m

Unit Weight: 0.1 kg

Complies With: IEC® 60947-1;IEC® 60998-2-1

DIAGRAMS

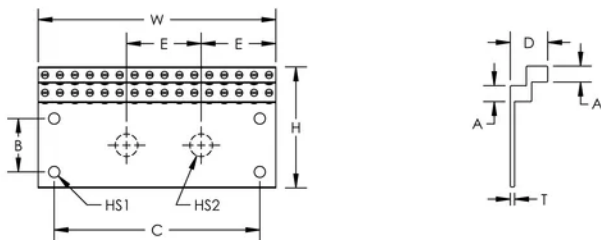

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE