

# FS Spacer Clamp, Snap Close



## CERTIFICATIONS



## FEATURES

Provides support for nVent ERIFLEX Flexibar and insulated braided conductors without damaging the insulation

Ensures correct spacing for optimum cooling

Supports up to four conductors in parallel

Easy to install

Halogen free

RoHS compliant

## SPECIFICATIONS

<b>Material:</b>	Polyamide
<b>Flammability Rating:</b>	UL® 94HB
<b>Working Temperature:</b>	-40 to 130 °C

Table 1/1


Catalog Number	Article Number	Conductor Width	Height (H)	Length (L)	Hole Size (HS)	Unit Weight
FS24	553550	24 mm Max	67 mm	30mm	7 mm	0.01 kg

CatalogNumber	Article Number	Conductor Width	Height (H)	Length (L)	Hole Size (HS)	Unit Weight
FS32	553560	32 mm Max	67 mm	38mm	7 mm	0.02 kg

## ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

## DIAGRAMS

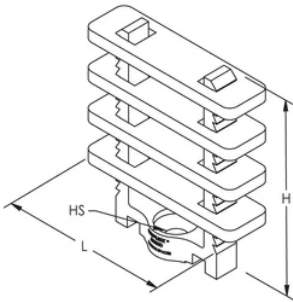

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**