


FS66S 19-inch Rack Angle

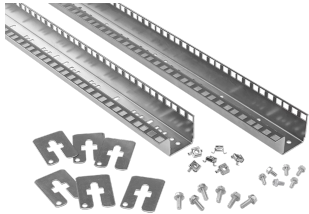

Rack angles accommodate 19-inch equipment. Furnished in pairs.

FEATURES

All necessary mounting hardware is included.

SPECIFICATIONS

Table 1/1					
Catalog Number	Material	Finish	Thickness	Fits Enclosure Height	Quick Ship
FMPM1800G000S	Mild Steel	Zinc Plated	2mm	1800mm	No
FMPM2100G000S	Mild Steel	Zinc Plated	2mm	2100mm	No
FMPM2300G000S	Mild Steel	Zinc Plated	2mm	2300mm	No
FMPM2200G000S	Mild Steel	Zinc Plated	2.5mm	2200mm	No
FMPM2000G000S	Mild Steel	Zinc Plated	2.5mm	2000mm	No
FMPM1500G000S	Mild Steel	Zinc Plated	2.5mm	1500mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE