


19" Front Panel, Vented, 1 U, 2.5 mm, Al, RAL 7035

CATALOG NUMBER

30702-056

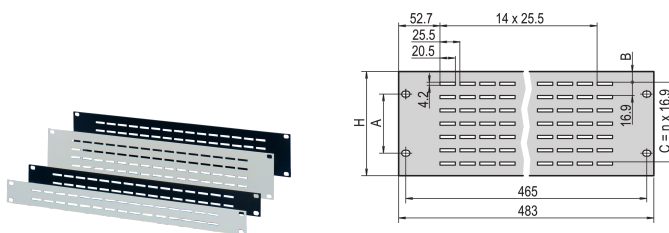

Vented front panels allows heat dissipation through holes.

CERTIFICATIONS



FEATURES

Vented front panels (Aluminum) allows heat dissipation

PRODUCT ATTRIBUTES

Rack Height: 1U

Accessory Type: Front panel

Finish: Powder Coated

Mounting: Screw-on Front

Package Quantity: 1

Front Finish: Painted

Rear Finish: Painted

Color Code: RAL 7035

EMC Shielding: No

Height (H): 43.6mm

Material: Aluminum

Product Type: Front Panel

Rack Width: 95HP

Type: 19" Front Panel


Width (W): 483mm

Net Weight: 0.121kg

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

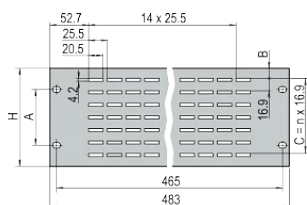

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE