


# U-profile Front Panel, Shieldable, D-Sub Cutouts

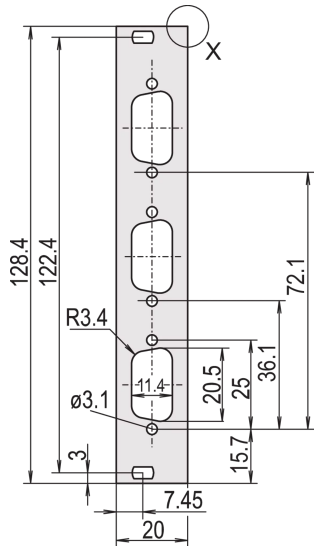

U-profile front panel with cutout for D-Sub connectors.  
Shieldable for textile EMC gasket.

## CERTIFICATIONS



## FEATURES

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

## SPECIFICATIONS

<b>Depth (D):</b>	2.5mm
<b>Rack Height:</b>	3U
<b>Rack Width:</b>	4HP
<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel without Handle

**EMC Shielding:** No (Retrofittable)

Table 1/2

Catalog Number	Package Quantity	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-749	1	Screw-on Front	Textile	Anodized	Conductive	(1) 9
30849-750	1	Screw-on Front	Textile	Anodized	Conductive	(2) 9
30849-751	1	Screw-on Front	Textile	Anodized	Conductive	(3) 9
30849-752	1	Screw-on Front	Textile	Anodized	Conductive	(1) 15
30849-753	1	Screw-on Front	Textile	Anodized	Conductive	(2) 15
30849-754	1	Screw-on Front	Textile	Anodized	Conductive	(1) 25
30849-755	1	Screw-on Front	Textile	Anodized	Conductive	(2) 25

Table 2/2

Catalog Number	Treated Edges	Complies With	Height (H)	Width (W)	Quick Ship
30849-749	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-750	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-751	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-752	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-753	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-754	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-755	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No

## ADDITIONAL PRODUCT DETAILS


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## DIAGRAMS

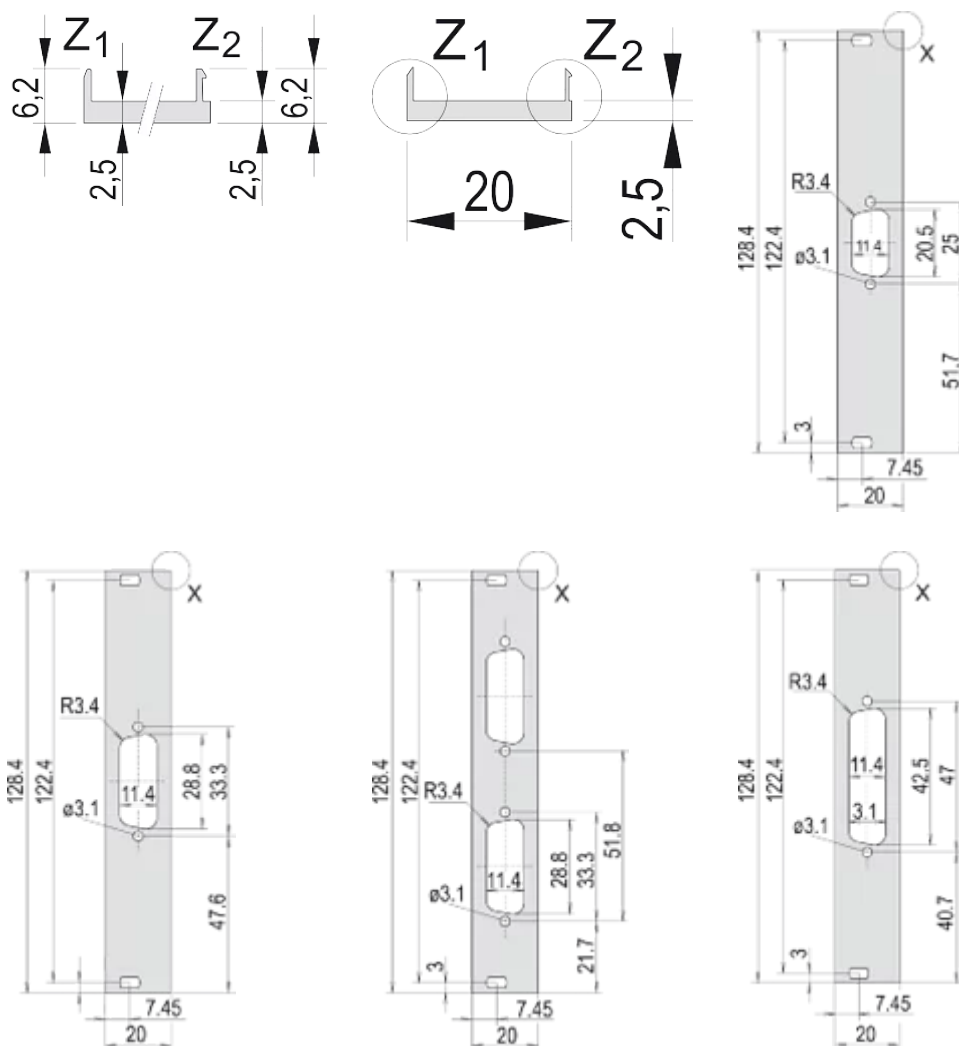

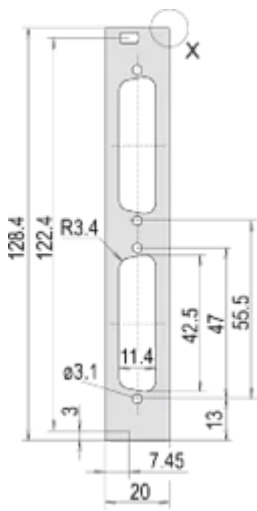

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**