


# Air Terminal Base, Stamped Ridge Mount, Imperial Thread

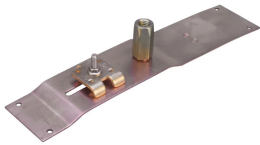

## CERTIFICATIONS



## FEATURES

For use on ridged roofs

For positive bolt tension cable clamping

## SPECIFICATIONS

**Conductor Size, UL:** Class 1 - Class 2 (4/0 Max)

Table 1/2

Catalog Number	Material	Finish	Thread Size (TS)	Hole Size (HS)	Depth (D)	Height (H)
LPA31512	Aluminum		1/2" UNC	5.08 mm	63.5mm	43.81 mm
LPA31558	Aluminum		5/8" UNC	5.08 mm	63.5mm	43.81 mm
LPA31212	Aluminum		1/2" UNC	5.08 mm	63.5mm	43.81 mm


CatalogNumber	Material	Finish	Thread Size (TS)	Hole Size (HS)	Depth (D)	Height (H)
LPA31258	Aluminum		5/8" UNC	5.08 mm	63.5mm	43.81 mm
LPC31212	Copper		1/2" UNC	5.08 mm	63.5mm	43.81 mm
LPC31238	Copper		3/8" UNC	5.08 mm	63.5mm	43.81 mm
LPC31258	Copper		5/8" UNC	5.08 mm	63.5mm	43.81 mm
LPC312L12	Copper	Tinned	1/2" UNC	5.08 mm	63.5mm	43.81 mm
LPC31512	Copper		1/2" UNC	5.08 mm	63.5mm	43.81 mm
LPC31538	Copper		3/8" UNC	5.08 mm	63.5mm	43.81 mm
LPC31558	Copper		5/8" UNC	5.08 mm	63.5mm	43.81 mm

Table 2/2

Catalog Number	Width (W)	Unit Weight
LPA31512	203.2 mm	0.16 kg
LPA31558	203.2 mm	0.16 kg
LPA31212	304.8 mm	0.18 kg
LPA31258	304.8 mm	0.18 kg
LPC31212	304.8 mm	0.43 kg
LPC31238	304.8 mm	0.43 kg
LPC31258	304.8 mm	0.43 kg
LPC312L12	304.8 mm	0.43 kg
LPC31512	203.2 mm	0.34 kg

Catalog Number	Width (W)	Unit Weight
LPC31538	203.2 mm	0.34 kg
LPC31558	203.2 mm	0.34 kg
 
## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**