 


Earthbridge B161, Four Stud, Insulated Cable, Straight



Earthbridges are assemblies made from a high-quality conductive earthpoint (connecting terminal) and various types of conductors. The nVent ERICO Cadweld exothermic connection process is used to combine them together, forming a highly corrosion resistant and long-lasting assembly.

DIAGRAMS



FEATURES

Long-lasting design

Low ground resistance and impedance

Superior electrical conductivity and resistance to corrosion

Electrically and mechanically robust and reliable

Easy to install

SPECIFICATIONS

- Earthpoint Type:** B161, Four Stud
- Material:** Copper
- Conductor Type:** Yellow-Green Insulated Cable, Straight

Table 1/3

Catalog Number	Article Number	Type	Conductor Size	Length (L)	Depth 1 (D1)	Depth 2 (D2)
----------------	----------------	------	----------------	------------	--------------	--------------

B16110C501	166520	BFCS	50 mm ² Stranded	1000mm	30mm	65mm
BF10C50S050H		BFCS	50 mm ² Stranded	500mm	30mm	65mm
B16110C5005	166510	BFCS	50 mm ² Stranded	500mm	30mm	65mm
BF10C50S100H C		BFCS	50 mm ² Stranded	1000mm	30mm	65mm

Table 2/3

Catalog Number	Article Number	Width 1 (W1)	Width 2 (W2)	Thread Size (TS)	Hole Quantity	Rebar Assembly Type
B16110C501	166520	30 mm	65 mm	M10	4	Cadweld or Clamp
BF10C50S050H		30 mm	65 mm	M10	4	Cadweld or Clamp
B16110C5005	166510	30 mm	65 mm	M10	4	Cadweld or Clamp
BF10C50S100H C		30 mm	65 mm	M10	4	Cadweld or Clamp

Table 3/3


Catalog Number	Article Number	Hardware Included	Earthbridge Application	Complies With
B16110C501	166520	Yes	Building	EN IEC® 62561-1 Class H 100kA
BF10C50S050H		Yes	Building	EN IEC® 62561-1 Class H 100kA
B16110C5005	166510	Yes	Building	EN IEC® 62561-1 Class H 100kA
BF10C50S100HC		Yes	Building	EN IEC® 62561-1 Class H 100kA

ADDITIONAL PRODUCT DETAILS

Includes (4) brass bolts, (4) brass washers, (4) plastic caps, and (1) protective label.

DB-16-C-70-S-050-C		
DB	Earth Point	DB: 1 hole BT: 2 holes BF: 4 holes LU: M16 lug TA: tape
16	Thread Size	10: M10 12: M12 16: M16 40: Tape 40x5mm 30: Tape 30x4mm
C	Conductor Type	K: Steel Rond C: Y/G Cable T: Steel Bar F: Steel Bar 4mm N: NYY-O Cable H: N2XH-0 Cable
70	Conductor Size	12: D12mm 16: D16mm 30: 30x4mm 40: 40x5mm 50: 50mm ² 70: 70mm ² 95: 95mm ²
S	Conductor Angle	S: 0° P: 90° A: 45°
050	Length (cm)	xxx
x	Termination (option if cable)	SR: Solid Round EP: Earthpoint perpendicular ES: Earthpoint straight TA: Tape of 100mm TP: Tape of 150mm LU: M16 lug
x	Bolts & Washer	- : No Hardware H: With Hardware
C	Packaging	- : by unit (Made-to-Stock) C: 5 pieces (Made-to-Order) G: 25 pieces (Made-to-Order)

DIAGRAMS

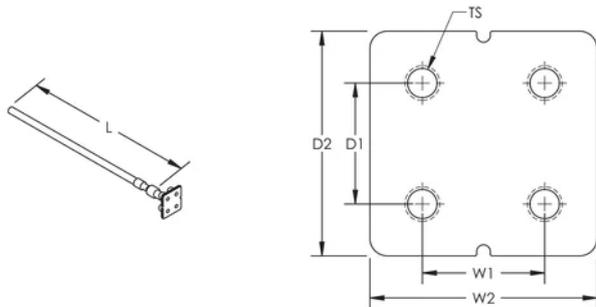

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE