

# Ground Rod Clamp, U-Bolt, Tinned, One Conductor



## CERTIFICATIONS



## FEATURES

Tinned finish provides a theft-deterrent appearance

Accepts conductors in both parallel and perpendicular orientations

## SPECIFICATIONS

**Material:** Bronze;Stainless Steel 304 (EN 1.4301)


**Finish:** Tinned

Table 1/1

Catalog Number	Ground Rod Diameter, Nominal	Conductor Size, UL
GC064	5/8" - 3/4"	#4 Sol - 2/0 Str, 16 mm <sup>2</sup> Str - 50 mm <sup>2</sup> Str
GC065	5/8" - 3/4"	2/0 Sol - 250 kcmil Str, 70 mm <sup>2</sup> Str - 120 mm <sup>2</sup> Str

Conductor Orientation (Parallel or Perpendicular)					
GC064		Conductor Size (Stranded)			
Nominal Ground Rod Diameter	16mm <sup>2</sup>	25mm <sup>2</sup>	35mm <sup>2</sup>	50mm <sup>2</sup>	70mm <sup>2</sup>
5/8" copper-bonded ground rod	Par.	Par.	Par.	Perp.	Perp.
5/8" galvanized/stainless steel ground rod	Par.	Par.	-	Perp.	Perp.
3/4" copper-bonded ground rod	Par.	-	-	Perp.	Perp.
3/4" galvanized/stainless steel ground rod	-	-	-	Perp.	-
GC065		Conductor Size (Stranded)			
Nominal Ground Rod Diameter	16mm <sup>2</sup>	25mm <sup>2</sup> -70mm <sup>2</sup>		95mm <sup>2</sup>	120mm <sup>2</sup>
5/8" copper-bonded ground rod	Par.	Both		Both	Par.
5/8" galvanized/stainless steel ground rod	Par.	Both		Both	Par.
3/4" copper-bonded ground rod	Par.	Both		Both	-
3/4" galvanized/stainless steel ground rod	Par.	Both		-	-

## DIAGRAMS

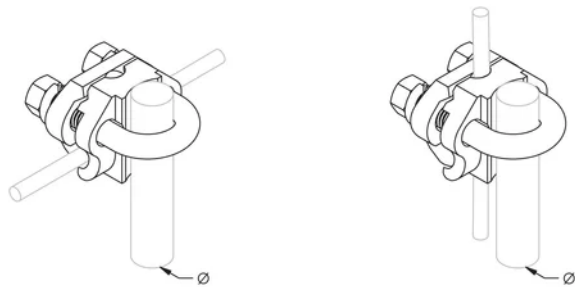

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**