

# Ground Rod Socket Driving Stud for Externally Threaded Ground Rods



## FEATURES

Used in conjunction with threaded couplers while driving threaded ground rods


## SPECIFICATIONS

**Material:** Steel

Table 1/1

Catalog Number	Article Number	Ground Rod Diameter, Nominal	Thread Size (TS)	Length (L)	Thread Length (TL)
158100	158100	0.88"	5/8" UNC	47.7mm	31.8mm
158110	158110	1"	3/4" UNC	57.2mm	38.1mm

## DIAGRAMS

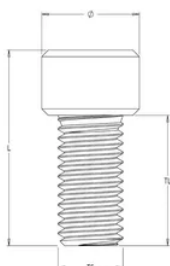

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**