


# Industrial Stack 2-Bolt Cable Fastener



## CERTIFICATIONS

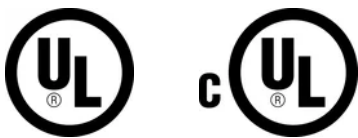

## FEATURES

Provides threaded attachment point for lightning conductors

## SPECIFICATIONS

**Material:** Brass  
**Conductor Size, UL:** Class 2 (4/0 Max)


Table 1/2

Catalog Number	Finish	Thread Size (TS)	Screw Length (L)	Height (H)	Width (W)	Unit Weight
LPC482SH	Bare	1/2" UNC	22.22mm	20.4 mm	53.8 mm	0.14 kg
LPC482LG	Bare	1/2" UNC	38.1mm	20.4 mm	53.8 mm	0.16 kg
LPLC482SH	Lead Covered	1/2" UNC	22.22mm	20.4 mm	53.8 mm	0.39 kg
LPLC482LG	Lead Covered	1/2" UNC	38.1mm	20.4 mm	53.8 mm	0.41 kg

Table 2/2

Catalog Number	Certifications
LPC482SH	E202878-Combined_CoC, E202878-Combined_CoC
LPC482LG	E202878-Combined_CoC, E202878-Combined_CoC
LPLC482SH	
LPLC482LG	

## DIAGRAMS

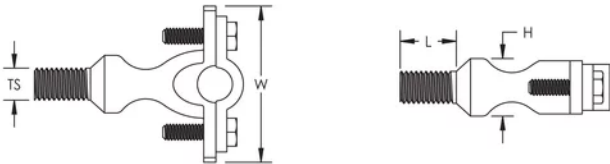

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**