


# Industrial Stack Bonding Assembly, Lug to Connector



## CERTIFICATIONS

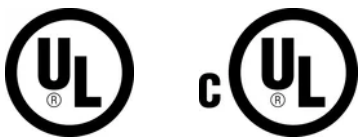

## FEATURES

Cast lug and clamp assembly for bonding conductors to structural features

## SPECIFICATIONS

**Material:** Copper

**Conductor Type:** LPC401

Table 1/2

Catalog Number	Finish	Cable Length	Hole Size (HS)	A	B	C
LPC465	Bare	0.91m	19.05 mm	72.14 mm	46.7 mm	104.8 mm
LPLC465	Lead Covered	0.91m	19.05 mm	72.14 mm	46.7 mm	104.8 mm


Table 2/2

Catalog Number	D	Unit Weight	Certifications
LPC465	54 mm	1.12 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPLC465	54 mm	2.12 kg	

## ADDITIONAL PRODUCT DETAILS

Where applicable, lead covering thickness is a minimum of 1/16" (1.59 mm) and is not included in the stated dimensions.
 
## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE