


nVent ERICO Cadweld Plus Rail Track Connector Bond Kit, Multi-Leg

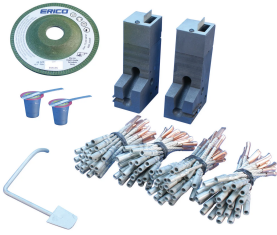

The nVent ERICO Cadweld Plus Rail Track Connector Bond Kit, Multi-leg, is intended to be welded to the web of the rail at the neutral axis. The kit has all the necessary components to establish a welded bond connection to the web of the rail. To ensure connection integrity, the attachment shall be made using nVent ERICO Cadweld Plus welding material. The multileg track connector was developed to allow multiple connections in tight spaces while maintaining rail integrity.

FEATURES

Provides multiple connection points via one track connection

Factory made nVent ERICO Cadweld connection

Reduces field labor and maintenance time on track

Easily make future connections in high-congestion areas

Provides unchanging electrical resistance

Superior corrosion resistance

Easy installation, with minimum installer training required

Simple and highly-portable installation equipment

Equally usable on old, worn, or new rails

Available as bond-only or incorporated in a Bond Kit including all necessary parts to ensure easy handling at jobsite

SPECIFICATIONS

Material: Copper Magnesium

Finish: Tinned

Table 1/2


Catalog Number	Bond Terminal Style	Conductor Size	Connector Conductor Size	Diameter (Ø)	Grinding Wheels Included	Length (L)
----------------	---------------------	----------------	--------------------------	--------------	--------------------------	------------

SBSTB3S2CR7 CWP	Tab	3/16" Bondstrand	3/16" Bondstrand	4.8 mm	Yes	50.8mm
SBSTB3E2CR7 CWP	Tab	3/16" Bondstrand	3/16" Bondstrand	4.8 mm	Yes	50.8mm

Table 2/2

Catalog Number	Length 1 (L1)	Length 2 (L2)	Overall Length metric	Handle Clamp
SBSTB3S2CR7CWP	63.5 mm	101.6 mm	177.8mm	C105B x 2, Sold Separately
SBSTB3E2CR7CWP	114.3 mm	114.3 mm	190.5mm	C105B x 2, Sold Separately

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE