


# Click-In Profiles, CLPK

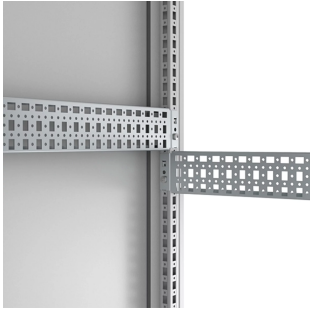

Additional accessories and electrical equipment can be mounted quickly and easily exactly where needed by using these click-in mounting profiles.

## FEATURES

---

Description: Universal profile for both depth and width fitting on the 25 mm DIN hole pattern of the enclosure's frame or in combination with the CLPF and VB profiles. The 75 mm wide profile is equipped with three rows of holes of which one is turned 90°. This makes it possible to mount the CLPF profiles in both directions. The CLPK can be secured by the use of self tapping screws.

Material: 1.5 mm zinc plated steel.

Pack quantity: 4 profiles.

SPECIFICATIONS

Thickness: 1.5mm  
Material: Mild Steel  
Finish: Zinc Plated

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Load Rating	Enclosure Material
CLPK1200	CLPK1200	74mm	1200mm	26mm	1200N	Mild Steel
CLPK300		74mm	300mm	26mm	2000N	Mild Steel
CLPK1000	CLPK1000	74mm	1000mm	26mm	1200N	Mild Steel
CLPK400	CLPK400	74mm	400mm	26mm	2000N	Mild Steel
CLPK500	CLPK500	74mm	500mm	26mm	2000N	Mild Steel
CLPK600	CLPK600	74mm	600mm	26mm	1600N	Mild Steel
CLPK800	CLPK800	74mm	800mm	26mm	1600N	Mild Steel

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE