


Elbow 90-Degree Tee-Cross Lay-in Galvanized

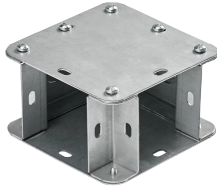

Lay-in Galvanized 90-Degree Elbow-Tee-Crosses are used for left or right 90-degree turns. Can be used as a tee or cross. Use with open adapter for cable entrance in top and bottom. Includes two closure plates.

FEATURES

Lay-in Galvanized 90-Degree Elbow-Tee-Crosses are used for left or right 90-degree turns

Can be used as a tee or cross. Use with open adapter for cable entrance in top and bottom

Includes two closure plates

SPECIFICATIONS

Finish: Galvanized
Material: Mild Steel

Table 1/1						
Catalog Number	Article Number	Type	Height	Width	Thickness	Quick Ship
F121290TXGV	88970	Elbow	305mm	305mm	1.9mm	No
F2290TXGV	87990	Elbow	64mm	64mm	1.52mm	No
F4490TXGV	88260	Elbow	102mm	102mm	1.52mm	No
F101090TXGV	45370	Elbow	254mm	254mm	1.9mm	No
F6690TXGV	88550	Elbow	152mm	152mm	1.52mm	No
F8890TXGV	88770	Elbow	203mm	203mm	1.9mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE