

CFFPW Tapered Plastic Screw-In Plug for A2 Couplers



FEATURES

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICATIONS

Material: Polyethylene

Table 1/2


Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Height (H)
EL12CFFPW	12 mm	#4	10M	59 mm	32 mm	23 mm
EL16CFFPW	16 mm	#5	15M	59 mm	36 mm	23 mm
EL20CFFPW	20 mm	#6	20M	59 mm	41 mm	23 mm
EL25CFFPW	25 mm	#8	25M	59 mm	46 mm	23 mm

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1(\varnothing 1)	Diameter 2(\varnothing 2)	Height (H)
EL28CFFPW	28 mm	#9	30M	59 mm	50 mm	23 mm

Table 2/2

Catalog Number	Thickness (T)	Color
EL12CFFPW	3 mm	Red
EL16CFFPW	3 mm	Black
EL20CFFPW	3 mm	Yellow
EL25CFFPW	3 mm	Red
EL28CFFPW	3 mm	Black

DIAGRAMS

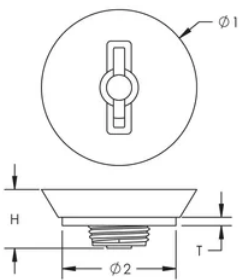

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE