

# ELCP Tapered Plastic Screw-In Plug for A2



## FEATURES

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Material:** High Density Polyethylene (HDPE)

Table 1/1


Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
ELCP12	12 mm	#4	10M	17 mm	10 mm	Red
ELCP16	16 mm	#5	15M	22 mm	15 mm	Black
ELCP20	20 mm	#6	20M	27 mm	15 mm	Yellow
ELCP22	22 mm	#7		30 mm	15 mm	Blue
ELCP25	25 mm	#8	25M	35 mm	15 mm	Red
ELCP28	28 mm	#9	30M	38 mm	15 mm	Black

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
ELCP32	32 mm	#10		44 mm	15 mm	Yellow
ELCP36	36 mm	#11	35M	48 mm	17 mm	Blue
ELCP40	40 mm			57 mm	17 mm	Green
ELCP43T	43 mm	#14	45M	57 mm	17 mm	Red
ELCP57T	57 mm	#18	55M	76 mm	17 mm	Blue

## ADDITIONAL PRODUCT DETAILS

ELCP12 is a push-in style plug.

## DIAGRAMS

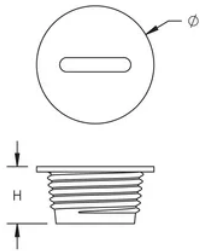

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**