


On Board Rack

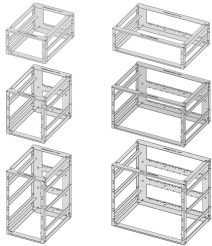

Suitable for ongoing vibrations, shock, high temperatures, and high humidity.

CERTIFICATIONS



FEATURES

For mobile railway applications

Suitable for ongoing vibrations, shock, high temperatures, and high humidity

Suitable for 1, 2, or 3 U SNCF subracks (NF F61-005, CF 60-002)

Rear side is equipped for standard connectors; crossbar can be custom-coded for the SNCF coding pins

Crossbar with integrated cable channel

Several racks can be stacked or fitted in rows

Produced using a welding process, certified to EN 15085 (CL2)

Stainless Steel welds passivated to prevent corrosion

SPECIFICATIONS

Static Load:	25kg
Depth:	341.8mm
Product Type:	Rack
Complies With:	SNCF NFF 61005; SNCF NFF 60002
Frame Material:	Steel

Table 1/2

Catalog Number	Rack Height	Height	Rack Width	Width	Package Quantity	Material
10170-017	9U	423.4mm	36HP	252.65mm	1	Stainless Steel
10170-016	9U	423.4mm	84HP	496.4mm	1	Stainless Steel
10170-015	3U	156.7mm	36HP	252.65mm	1	Stainless Steel
10170-012	6U	290mm	84HP	496.4mm	1	Stainless Steel
10170-014	3U	156.7mm	84HP	496.4mm	1	Stainless Steel
10170-013	6U	290mm	36HP	252.65mm	1	Stainless Steel

Table 2/2

Catalog Number	Quick Ship
10170-017	No
10170-016	No
10170-015	No
10170-012	No
10170-014	No
10170-013	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE