


Frame Type Plug-In Unit Extruded Side Panel, With Cooling Fins, Right, 6 U, D = 167 mm

CATALOG NUMBER

34812-701

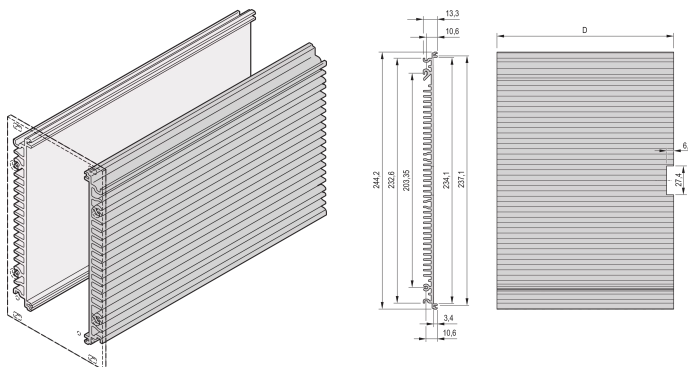

Side Panel for frame type plug-in unit, extruded with cooling Fins. The cooling Fins enable additional heat dissipation via the cooling Fins.

CERTIFICATIONS



FEATURES

The external dimensions (8 ... 42 HP) are unchanged; the available space inside is reduced widthwise by the cooling Fins

With 10 W installed heat dissipation the interior temperature in the module is reduced by about 5 °C

Side Panel with cooling Fins for a frame-type plug-in unit (Al extrusion). The surface is 65% greater than with a side Panel without cooling Fins

PRODUCT ATTRIBUTES

Rack Height: 6U
Design Feature: Right
Package Quantity: 1
PCB Length metric: 167mm
Finish: Passivated
Length: 160mm
Material: Aluminum
Product Type: Side Panel
Type: Side Panel
Gross Weight: 0.477kg

ADDITIONAL PRODUCT DETAILS

Side Panels with and without cooling Fins can be combined. Frame type plug-in unit consists of: 2 side Panels, front Panel with handle, rear Panel, cover plate, base plate, fixing kit.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	+971.4.378.1700
Chat with us:	Betschdorf, France	Qingdao, China	Bangalore, India
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	+91.80.6715.2001
	Warsaw, Poland	Singapore	Istanbul, Turkey
	+48.22.209.98.35	+65.6768.5800	+90.216.250.7374
	Assago, Italy	Shin-Yokohama, Japan	Chat with us:
	+39.02.932.7141	+81.45.476.0271	nvent.com/schroff
	Chat with us:	Chat with us:	
	nvent.com/schroff	nvent.com/schroff	



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE