


# Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

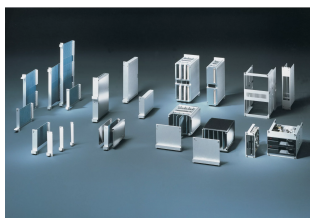

## CERTIFICATIONS



## FEATURES

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel for Handle (PIU)
<b>EMC Shielding:</b>	No (Retrofittable)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	EMC Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile	Anodized

CatalogNumber	Rack Width	Package Quantity	Handle Type	Mounting	EMC Gasket Type	Front Finish
30849-154	4HP	1	XL	Screw-on Front	Textile	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	Depth (D)	Height (H)	Rack Height
30849-153	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Catalog Number	Width (W)	Quick Ship
30849-153	20mm	No
30849-154	20mm	No
30849-155	40.3mm	No



### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**