


# RatiopacPRO EMC Front Panel, Slotted, Shielded

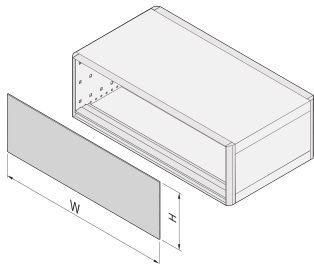

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

## CERTIFICATIONS



## FEATURES

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-603	3U	28HP	1	Anodized	Conductive	No
24572-604	3U	42HP	1	Anodized	Conductive	No

CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-605	3U	63HP	1	Anodized	Conductive	No
24572-606	3U	84HP	1	Anodized	Conductive	No
24572-607	4U	28HP	1	Anodized	Conductive	No
24572-608	4U	42HP	1	Anodized	Conductive	No
24572-609	4U	63HP	1	Anodized	Conductive	No
24572-610	4U	84HP	1	Anodized	Conductive	No
24572-599	2U	28HP	1	Anodized	Conductive	No
24572-600	2U	42HP	1	Anodized	Conductive	No
24572-601	2U	63HP	1	Anodized	Conductive	No
24572-602	2U	84HP	1	Anodized	Conductive	No

Table 2/2				
Catalog Number	Depth	Height	Width	Quick Ship
24572-603	2.5mm	128.4mm	141.9mm	No
24572-604	2.5mm	128.4mm	213.2mm	No
24572-605	2.5mm	128.4mm	319.7mm	No
24572-606	2.5mm	128.4mm	426.4mm	No
24572-607	2.5mm	172.9mm	141.9mm	No
24572-608	2.5mm	172.9mm	213.2mm	No
24572-609	2.5mm	172.9mm	319.7mm	No

Catalog Number	Depth	Height	Width	Quick Ship
24572-610	2.5mm	172.9mm	426.4mm	No
24572-599	2.5mm	84mm	141.9mm	No
24572-600	2.5mm	84mm	213.2mm	No
24572-601	2.5mm	84mm	319.7mm	No
24572-602	2.5mm	84mm	426.4mm	No

## ADDITIONAL PRODUCT DETAILS

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**