


# Solder Strip Conductor

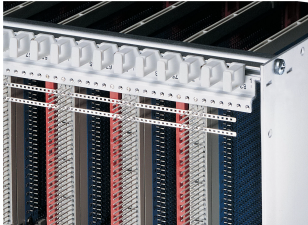

Efficient linking of connections in the same grid and with the same potential. Can be used for connectors in accordance with EN 60603-2 (DIN 41612).

## CERTIFICATIONS



## FEATURES

Efficient linking of connections in the same grid and with the same potential

Also suitable for EN 60603 (DIN 41612) connectors with wire-wrap pin

## SPECIFICATIONS

<b>Product Type:</b>	Busbar
<b>Material:</b>	Copper
<b>Works With:</b>	Front Panels
<b>Finish:</b>	Tin Plated

Table 1/1

Catalog Number	Package Quantity	Connection Type	Quick Ship
60800-064	1	Pins, 0.6 x 0.6 mm	No
60800-080	1	Pins, 1.0 x 1.0 mm	No

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**