

Offset Mounting Base for Cable Clamp



FEATURES

Allows cable to be installed at a fixed distance from concrete when using a cable clamp

Can be used in both directions allowing for multiple offset distances

Halogen free

UV-stabilized

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Temperature	Height (H)	Width (W)	Depth (D)
SCFS	800054	Polypropylene	-10 to 85 °C	13 mm	22 mm	10mm

Table 2/2

Catalog Number	Article Number	A	B
SCFS	800054	8 mm	15 mm

DIAGRAMS

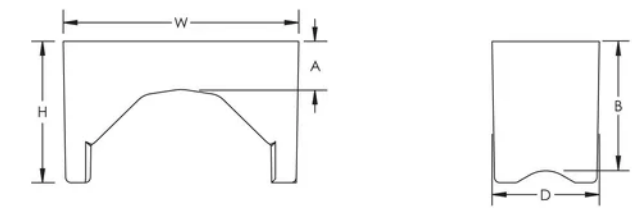

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

