


# DH Distance Holder and Spacer

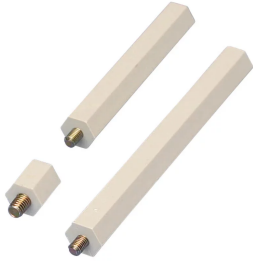

## CERTIFICATIONS



## FEATURES

To make higher plates, screens or profiles

Male-female allowing stable mounting

Electrotechnical applications

## SPECIFICATIONS

<b>Insulation Voltage:</b>	1000V
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polystyrene
<b>Flammability Rating:</b>	UL® 94HB
<b>Temperature:</b>	80 °C Max

Table 1/2

Catalog Number	Article Number	Thread Size (TS)	Thread Length (TL)	Thread Depth (TD)	Length (L)	Width (W)
DH15M5	560660	M5	7mm	7mm	15mm	13 mm


CatalogNumber	Article Number	Thread Size (TS)	Thread Length (TL)	Thread Depth (TD)	Length (L)	Width (W)
DH15M6	560740	M6	7mm	8mm	15mm	13 mm
DH20M5	560670	M5	7mm	7mm	20mm	13 mm
DH20M6	560750	M6	7mm	8mm	20mm	13 mm
DH30M5	560600	M5	7mm	7mm	30mm	13 mm
DH30M6	560700	M6	7mm	8mm	30mm	13 mm
DH45M5	560610	M5	7mm	7mm	45mm	13 mm
DH45M6	560710	M6	7mm	8mm	45mm	13 mm
DH55M5	560620	M5	7mm	7mm	55mm	13 mm
DH70M5	560630	M5	7mm	7mm	70mm	13 mm
DH120M5	560650	M5	7mm	7mm	120mm	13 mm
DH70M6	560720	M6	7mm	8mm	70mm	13 mm
DH85M5	560640	M5	7mm	7mm	85mm	13 mm
DH120M6	560730	M6	7mm	8mm	120mm	13 mm

Table 2/2

Catalog Number	Article Number	Unit Weight
DH15M5	560660	0 kg
DH15M6	560740	0 kg
DH20M5	560670	0.01 kg
DH20M6	560750	0.01 kg

Catalog Number	Article Number	Unit Weight
DH30M5	560600	0.01 kg
DH30M6	560700	0.01 kg
DH45M5	560610	0.01 kg
DH45M6	560710	0.01 kg
DH55M5	560620	0.01 kg
DH70M5	560630	0.01 kg
DH120M5	560650	0.02 kg
DH70M6	560720	0.02 kg
DH85M5	560640	0.02 kg
DH120M6	560730	0.04 kg
 
## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**