

UFS nVent ERIFLEX Flexibar and IBSB Support Kit

Power Utilities



CERTIFICATIONS



FEATURES

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Conductor Thickness	Conductor Width	Height (H)	Width (W)	A
UFS-KIT	553590	2 – 8 mm	15.5 – 120.0 mm	57.50 mm	30 mm	24 mm


Table 2/2

Catalog Number	Article Number	B	Unit Weight
UFS-KIT	553590	15 mm	2.300 kg

ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

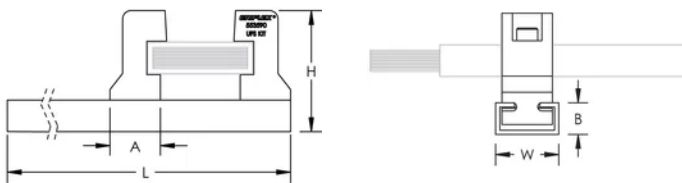

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE