


# Comptec 19" Desktop Case, Unshielded

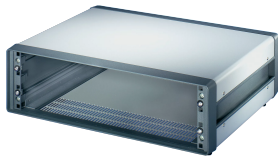

The nVent SCHROFF Comptec case is compatible with a 19" cabinet and is used to house assemblies such as 19" subracks, 19" fan trays or 19" front panels. This case is also typically used for desktop applications.

## CERTIFICATIONS



## FEATURES

Desktop case (pre-fitted)

Unshielded

Ventilation slits in base plate

Front and rear frames in die-cast Al

Top cover, base plate and rear panel in steel

Conforms with DIN EN 62368-1

## SPECIFICATIONS

**Product Type:** Case  
**Type:** Case for 19" Subrack and 19" Chassis  
**Product Family:** Comptec

Table 1/3

| Catalog Number | Rack Height | Height | Rack Width | Depth | Material        | Package Quantity |
|----------------|-------------|--------|------------|-------|-----------------|------------------|
| 10225-601      | 3U          | 153mm  | 84HP       | 300mm | Aluminum, Steel | 1                |

| CatalogNumber | Rack Height | Height | Rack Width | Depth | Material        | Package Quantity |
|---------------|-------------|--------|------------|-------|-----------------|------------------|
| 10225-602     | 4U          | 198mm  | 84HP       | 300mm | Aluminum, Steel | 1                |
| 10225-604     | 6U          | 286mm  | 84HP       | 300mm | Aluminum, Steel | 1                |
| 10225-612     | 3U          | 153mm  | 84HP       | 400mm | Aluminum, Steel | 1                |
| 10225-613     | 4U          | 198mm  | 84HP       | 400mm | Aluminum, Steel | 1                |
| 10225-615     | 6U          | 286mm  | 84HP       | 400mm | Aluminum, Steel | 1                |
| 10225-616     | 7U          | 331mm  | 84HP       | 400mm | Aluminum, Steel | 1                |
| 10225-618     | 9U          | 420mm  | 84HP       | 400mm | Aluminum, Steel | 1                |
| 10225-623     | 3U          | 153mm  | 84HP       | 500mm | Aluminum, Steel | 1                |
| 10225-624     | 4U          | 198mm  | 84HP       | 500mm | Aluminum, Steel | 1                |
| 10225-626     | 6U          | 286mm  | 84HP       | 500mm | Aluminum, Steel | 1                |
| 10225-627     | 7U          | 331mm  | 84HP       | 500mm | Aluminum, Steel | 1                |
| 10225-629     | 9U          | 420mm  | 84HP       | 500mm | Aluminum, Steel | 1                |
| 10225-637     | 6U          | 286mm  | 84HP       | 600mm | Aluminum, Steel | 1                |
| 10225-638     | 7U          | 331mm  | 84HP       | 600mm | Aluminum, Steel | 1                |
| 10225-640     | 9U          | 420mm  | 84HP       | 600mm | Aluminum, Steel | 1                |
| 10225-667     | 9U          | 420mm  | 84HP       | 400mm | Aluminum        | 1                |
| 10225-670     | 12U         | 553mm  | 84HP       | 400mm | Aluminum        | 1                |
| 10225-682     | 9U          | 420mm  | 84HP       | 500mm | Aluminum        | 1                |

| CatalogNumber | Rack Height | Height | Rack Width | Depth | Material | Package Quantity |
|---------------|-------------|--------|------------|-------|----------|------------------|
| 10225-685     | 12U         | 553mm  | 84HP       | 500mm | Aluminum | 1                |
| 10225-693     | 9U          | 420mm  | 84HP       | 600mm | Aluminum | 1                |
| 10225-696     | 12U         | 553mm  | 84HP       | 600mm | Aluminum | 1                |

| Table 2/3      |               |              |                          |                |                 |               |
|----------------|---------------|--------------|--------------------------|----------------|-----------------|---------------|
| Catalog Number | Usable Height | Usable Width | Front Frame Construction | Cooling Option | Complies With   | EMC Shielding |
| 10225-601      | 134.2mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-602      | 178.7mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-604      | 267.6mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-612      | 134.2mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-613      | 178.7mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-615      | 267.6mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-616      | 312mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-618      | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-623      | 134.2mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-624      | 178.7mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-626      | 267.6mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-627      | 312mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-629      | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |

| CatalogNumber | Usable Height | Usable Width | Front Frame Construction | Cooling Option | Complies With   | EMC Shielding |
|---------------|---------------|--------------|--------------------------|----------------|-----------------|---------------|
| 10225-637     | 267.6mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-638     | 312mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-640     | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-667     | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-670     | 534mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-682     | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-685     | 534mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-693     | 400.9mm       | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |
| 10225-696     | 534mm         | 451mm        | Single Piece             | No             | IEC 60297-3-100 | No            |

Table 3/3

| Catalog Number | Finish        | Protection Rating | Static Load | Width | Quick Ship |
|----------------|---------------|-------------------|-------------|-------|------------|
| 10225-601      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-602      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-604      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-612      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-613      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-615      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-616      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-618      | Powder Coated | IP20              | 40kg        | 520mm | No         |

| Catalog Number | Finish        | Protection Rating | Static Load | Width | Quick Ship |
|----------------|---------------|-------------------|-------------|-------|------------|
| 10225-623      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-624      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-626      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-627      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-629      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-637      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-638      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-640      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-667      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-670      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-682      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-685      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-693      | Powder Coated | IP20              | 40kg        | 520mm | No         |
| 10225-696      | Powder Coated | IP20              | 40kg        | 520mm | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**