

# Quick Strut Nut



## FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

Pre-assembled slide nut ready to use out of the box

Spring retains assembly in place until hardware is tightened

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	A	B	C	Torque (TQ)
QSNM10EG	592920	10	8 mm	4 mm	41 mm	55 N·m
QSNM12EG	592930	12	8 mm	4 mm	41 mm	
QSNM6EG	592900	6	6 mm	4 mm	41 mm	
QSNM8EG	592910	8	6 mm	4 mm	41 mm	28 N·m

Table 2/2


Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
----------------	----------------	--------------------	--------------------	--------------------

QSNM10EG	592920	4400N	4400N	4900N
QSNM12EG	592930	4400N	4700N	4900N
QSNM6EG	592900	2000N	2000N	2000N
QSNM8EG	592910	3300N	3300N	3300N

**ADDITIONAL PRODUCT DETAILS**

Static Load 1 represents 1.5 mm strut channel thickness. Static Load 2 represents 2.0 mm strut channel thickness. Static Load 3 represents 2.5 mm strut channel thickness.

**DIAGRAMS**

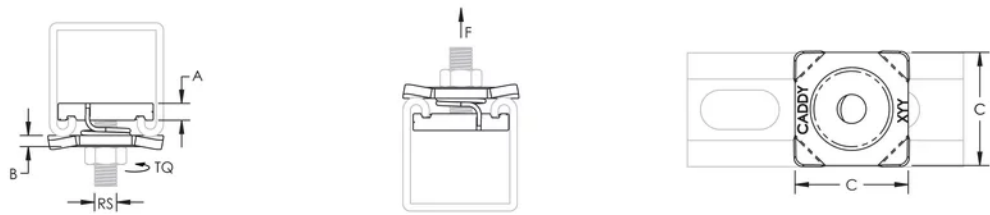

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

