 


# PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

## FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Design Version:** European (Specialty Materials)

**Material:** High Density Polyethylene (HDPE);Steel

Table 1/2


| Catalog Number | Article Number | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Diameter (Ø) | Height (H) |
|----------------|----------------|--------------------|----------------|--------------------|--------------|------------|
| EL1416PFF      | 153810         | 14 mm, 16 mm       | #5             | 15M                | 65 mm        | 15 mm      |
| EL1012PFF      | 153800         | 10 mm, 12 mm       | #3, #4         | 10M                | 65 mm        | 15 mm      |
| EL2225PFF      | 153840         | 22 mm, 25 mm       | #7, #8         | 25M                | 95 mm        | 18 mm      |
| EL2830PFF      | 153850         | 28 mm, 30 mm       | #9             | 30M                | 95 mm        | 18 mm      |

| CatalogNumber | Article Number | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Diameter (Ø) | Height (H) |
|---------------|----------------|--------------------|----------------|--------------------|--------------|------------|
| EL20PFF       | 153830         | 20 mm              | #6             | 20M                | 75 mm        | 18 mm      |
| EL18PFF       | 153820         | 18 mm              |                |                    | 75 mm        | 18 mm      |
| EL32PFF       | 153860         | 32 mm              | #10            |                    | 95 mm        | 18 mm      |
| EL40PFF       | 153870         | 40 mm              |                |                    | 95 mm        | 18 mm      |

Table 2/2

| Catalog Number | Article Number | Color  |
|----------------|----------------|--------|
| EL1416PFF      | 153810         | Black  |
| EL1012PFF      | 153800         | Red    |
| EL2225PFF      | 153840         | Red    |
| EL2830PFF      | 153850         | Black  |
| EL20PFF        | 153830         | Yellow |
| EL18PFF        | 153820         | White  |
| EL32PFF        | 153860         | Yellow |
| EL40PFF        | 153870         | Green  |

## DIAGRAMS

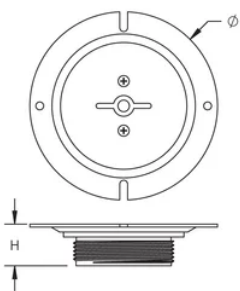

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**