


# EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

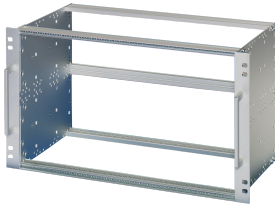

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

## CERTIFICATIONS



## FEATURES

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

## SPECIFICATIONS

|                       |                 |
|-----------------------|-----------------|
| <b>Static Load:</b>   | 15kg            |
| <b>Material:</b>      | Aluminum        |
| <b>EMC Shielding:</b> | No              |
| <b>Product Type:</b>  | Subrack/Chassis |

Table 1/3

| Catalog Number | Rack Height | Depth | Package Quantity | For Mounting | Board Depth | EMC Gasket Type |
|----------------|-------------|-------|------------------|--------------|-------------|-----------------|
| 21500-077      | 3U          | 235mm | 1                | Backplane    | 220mm       | Textile         |
| 21500-078      | 6U          | 235mm | 1                | Backplane    | 220mm       | Textile         |

Table 2/3

| Catalog Number | Shock and Vibration Tolerance | Handle Included | Mounting | Complies With                          | Finish               | Rack Width |
|----------------|-------------------------------|-----------------|----------|----------------------------------------|----------------------|------------|
| 21500-077      | 5g (force)                    | Yes             | Rack     | IEC 60297-3-103, EN 50155 part 12.2.11 | Anodized, Passivated | 84HP       |
| 21500-078      | 5g (force)                    | Yes             | Rack     | IEC 60297-3-103, EN 50155 part 12.2.11 | Anodized, Passivated | 84HP       |

Table 3/3

| Catalog Number | Quick Ship |
|----------------|------------|
| 21500-077      | No         |
| 21500-078      | No         |

## ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**