

112 Loop Hanger with Flared Edges



CERTIFICATIONS



FEATURES

For steel and CPVC pipe

Flared edges help to protect plastic pipe

An integral fold-over washer (pipe sizes 2 1/2" to 8")

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	A	B
1120050EG		15	21 mm	3/8"	70.7 mm	29.2 mm
1120075EG		20	27 mm	3/8"	76.4 mm	32.2 mm
1120100EG		25	34 mm	3/8"	83.7 mm	36.2 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	A	B
1120125EG		32	43 mm	3/8"	92.1 mm	40.2 mm
1120150EG		40	48 mm	3/8"	98.2 mm	43.2 mm
1120200EG		50	60 mm	3/8"	110.2 mm	49.2 mm
1120250EG		65	76 mm	3/8"	138.2 mm	70.2 mm
1120300EG		80	89 mm	3/8"	154.1 mm	78.2 mm
1120400EG		100	114 mm	3/8"	193.8 mm	105.2 mm
112M0050EG	297860	15	21.3 mm	M10	70.7 mm	29.2 mm
1120500EG		125	140 mm	1/2"	236.2 mm	125.9 mm
1120600EG		150	165 mm	1/2"	262.7 mm	138.9 mm
1120800EG		200	219 mm	1/2"	337.6 mm	187.9 mm
112B0500EG		125	141 mm	1/2"	236.2 mm	125.9 mm
112B0600EG		150	165 mm	1/2"	262.7 mm	138.9 mm
112B0800EG		200	219 mm	1/2"	337.6 mm	187.9 mm
112M0100EG	297880	25	26.9 mm	M10	83.8 mm	36.2 mm
112M0125EG	297890	32	42.4 mm	M10	92.1 mm	40.2 mm
112M0150EG	297900	40	48.3 mm	M10	98.2 mm	43.2 mm
112M0200EG	297910	50	60.3 mm	M10	110.2 mm	49.2 mm
112M0075EG	297870	20	26.9 mm	M10	76.4 mm	32.2 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	A	B
112M0250EG	297920	65	76.1 mm	M10	138.2 mm	70.2 mm
112M0300EG	297930	80	88.9 mm	M10	154.1 mm	78.2 mm
112M0400EG	297940	100	114.3 mm	M10	193.8 mm	105.2 mm
112M0600EG	297960	150	165 mm	M12	262.7 mm	138.9 mm
112M0500EG	297950	125	141 mm	M12	236.2 mm	125.9 mm
112M0800EG	297970	200	219.1 mm	M12	337.6 mm	187.9 mm


Table 2/2

Catalog Number	Article Number	C	Static Load	Certifications
1120050EG		26.2 mm	1334N	UL, cUL
1120075EG		26.5 mm	1334N	UL, FM Approved, Pipe Hanger Components, cUL
1120100EG		27.1 mm	1334N	UL, FM Approved, Pipe Hanger Components, cUL
1120125EG		26.7 mm	1334N	UL, FM Approved, Pipe Hanger Components, cUL
1120150EG		26.7 mm	1334N	UL, FM Approved, Pipe Hanger Components, cUL
1120200EG		26.7 mm	1334N	UL, FM Approved, Pipe Hanger Components, cUL
1120250EG		41.3 mm	2340N	UL, FM Approved, Pipe Hanger Components, cUL
1120300EG		41.4 mm	2340N	UL, FM Approved, Pipe Hanger Components, cUL
1120400EG		55.7 mm	3780N	UL, FM Approved, Pipe Hanger Components, cUL

Catalog Number	Article Number	C	Static Load	Certifications
112M0050EG	297860	26.2 mm	1330N	UL, cUL
1120500EG		65.4 mm	3780N	UL, FM Approved, Pipe Hanger Components, cUL
1120600EG		64.9 mm	3500N	UL, FM Approved, Pipe Hanger Components, cUL
1120800EG		88.5 mm	6000N	UL, FM Approved, Pipe Hanger Components, cUL
112B0500EG		65.4 mm	4440N	
112B0600EG		64.9 mm	4440N	
112B0800EG		88.5 mm	4440N	
112M0100EG	297880	27.1 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0125EG	297890	26.7 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0150EG	297900	26.7 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0200EG	297910	26.7 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0075EG	297870	26.5 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0250EG	297920	41.3 mm	2340N	UL, FM Approved, Pipe Hanger Components, cUL
112M0300EG	297930	41.4 mm	2340N	UL, FM Approved, Pipe Hanger Components, cUL
112M0400EG	297940	55.7 mm	2890N	UL, FM Approved, Pipe Hanger Components, cUL

Catalog Number	Article Number	C	Static Load	Certifications
112M0600EG	297960	64.9 mm	4450N	UL, FM Approved, Pipe Hanger Components, cUL
112M0500EG	297950	65.4 mm	2890N	UL, FM Approved, Pipe Hanger Components, cUL
112M0800EG	297970	88.5 mm	6000N	UL, FM Approved, Pipe Hanger Components, cUL

DIAGRAMS

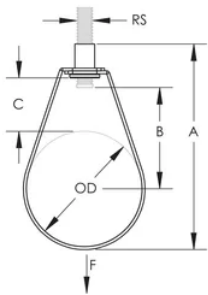

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

