

Cathodic Bonding Strap, 2 Holes



FEATURES

Allows electrical bonding across joints of steel pipe

Used to bond across standard mechanical joints or across "Dresser Type" joints when the coupling does not have to be bonded

Approximate electrical equivalent of a 1/0 conductor

Made of soft copper for easy forming

nVent ERICO Cadweld connections to pipe require a CA15 welding material


SPECIFICATIONS

Material: Copper

Table 1/1

Catalog Number	Length (L)	Width (W)	Thickness (T)	Hole Size (HS)	A	B
CAB496A44B0	330.2mm	31.75 mm	1.59 mm	12.7 mm	279.4 mm	25.4 mm
CAB496A32B0	254mm	31.75 mm	1.59 mm	12.7 mm	203.2 mm	25.4 mm
CAB496A36B0	279.4mm	31.75 mm	1.59 mm	12.7 mm	228.6 mm	25.4 mm
CAB496A64B0	457.2mm	31.75 mm	1.59 mm	12.7 mm	406.4 mm	25.4 mm

DIAGRAMS

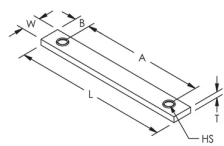

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE