

# Glued Clip Kit



## FEATURES

Glued rail clips eliminate the need to drill any support where the clips need to be fixed, respecting the support integrity and improving safety

No tools needed; pre-applied hard-bonding glue makes installation easy and efficient

Resistant to corrosion-causing agents, including U.V., weather conditions, oil, greases, gasoline, solvents, rain and water

Helps increase lifetime of attached cable, reducing total project cost

Versatile base can accommodate different sizes of clips for different sizes of conductors and is usable for longitudinal or transversal cable applications

Each kit includes one container of adhesive suitable for a 10.1 oz. (300 ml) dispensing gun

Dispensing gun not included

## SPECIFICATIONS

**Temperature:** -40 to 93 °C

Table 1/2

| Catalog Number | Article Number | Diameter (Ø) | Length (L) | Width (W) | Hole Size (HS) | Number of Base Plates Included |
|----------------|----------------|--------------|------------|-----------|----------------|--------------------------------|
| GCHSC67        | 186005         | 6 - 7 mm     | 100mm      | 40 mm     | 7 mm           | 30                             |
| GCHSC1011      | 186025         | 10 - 11 mm   | 100mm      | 40 mm     | 7 mm           | 30                             |
| GCHSC1214      | 186035         | 12 - 14 mm   | 100mm      | 40 mm     | 7 mm           | 30                             |

| CatalogNumber | Article Number | Diameter (Ø) | Length (L) | Width (W) | Hole Size (HS) | Number ofBase PlatesIncluded |
|---------------|----------------|--------------|------------|-----------|----------------|------------------------------|
| GCHSC1518     | 186045         | 15 - 18 mm   | 100mm      | 40 mm     | 7 mm           | 30                           |
| GCHSC1924     | 186055         | 19 - 24 mm   | 100mm      | 40 mm     | 7 mm           | 30                           |
| GCHSC2530     | 186065         | 25 - 30 mm   | 100mm      | 40 mm     | 7 mm           | 30                           |
| GCHSC78       | 187745         | 7 - 8 mm     | 100mm      | 40 mm     | 7 mm           | 30                           |
| GCHSC89       | 186015         | 8 - 9 mm     | 100mm      | 40 mm     | 7 mm           | 30                           |
| GCHSC910      | 187785         | 9 - 10 mm    | 100mm      | 40 mm     | 7 mm           | 30                           |


Table 2/2

| Catalog Number | Article Number | Number of Clips Included | Clips Per Base Plate |
|----------------|----------------|--------------------------|----------------------|
| GCHSC67        | 186005         | 120                      | 4 Max                |
| GCHSC1011      | 186025         | 120                      | 4 Max                |
| GCHSC1214      | 186035         | 120                      | 4 Max                |
| GCHSC1518      | 186045         | 90                       | 3 Max                |
| GCHSC1924      | 186055         | 90                       | 3 Max                |
| GCHSC2530      | 186065         | 60                       | 2 Max                |
| GCHSC78        | 187745         | 120                      | 4 Max                |
| GCHSC89        | 186015         | 120                      | 4 Max                |
| GCHSC910       | 187785         | 120                      | 4 Max                |

## ADDITIONAL PRODUCT DETAILS

3-clip configuration shown. 1- to 4-clip configurations also available.

DIAGRAMS

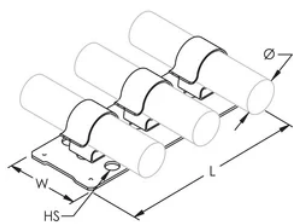

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE