


Rail Stub End Bond Kit, Power, W Style

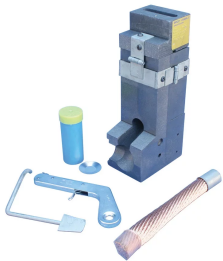

FEATURES

- Provides unchanging electrical resistance
- Superior corrosion resistance
- Easy installation, with minimum installer training required
- Simple and highly-portable installation equipment
- Equally usable on old, worn, or new rails
- Highly durable
- Includes ropelay copper cable for maximum flexibility
- Available as bond-only or incorporated in a Bond Kit including all necessary parts to ensure easy handling at jobsite

SPECIFICATIONS

Bond Terminal Style: W


Table 1/1

Catalog Number	Material	Finish	Conductor Size	Length (L)	Diameter (Ø)
PBW32W9WS	Copper, Copper Alloy	Bare, Tinned	250 kcmil Ropelay	228.6mm	14.6 mm
PBW33S9WS	Copper, Steel	Bare, Copper Plated	500 kcmil Ropelay	228.6mm	20.7 mm

ADDITIONAL PRODUCT DETAILS

Kits include: (50) bonds, (50) F80 alloy welding material, (1) replacement mold, (1) flint ignitor, and (1) mold cleaner.

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE