


# TFP Exhaust Grilles

Type 1 or Type 12 exhaust option for TFP Filter Fans

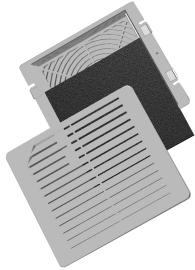

## FEATURES

TFP Exhaust Grilles includes standard replacement filters that are washable foam (Type 1) or disposable (Type 12)

To maintain UL Type 12 rating on the enclosure, UL Type 12 filters must be used on the fan package inlet

## SPECIFICATIONS

| Table 1/1      |                |        |       |       |                     |              |
|----------------|----------------|--------|-------|-------|---------------------|--------------|
| Catalog Number | Article Number | Height | Width | Depth | Material            | Finish       |
| TEP4           | 12774          | 159mm  | 186mm | 35mm  | Composite           | Smooth Matte |
| TEP4UL12       | 12777          | 159mm  | 186mm | 35mm  | Composite           | Smooth Matte |
| TEP6           | 12775          | 197mm  | 224mm | 32mm  | Composite           | Smooth Matte |
| TEP6UL12       | 12778          | 197mm  | 224mm | 32mm  | Composite           | Smooth Matte |
| TEP6SS         | 11231          | 197mm  | 224mm | 32mm  | Stainless Steel 304 | Brushed      |
| TEP10          | 12776          | 299mm  | 329mm | 34mm  | Composite           | Smooth Matte |
| TEP10UL12      | 12781          | 299mm  | 329mm | 34mm  | Composite           | Smooth Matte |
| TEP10SS        | 11232          | 299mm  | 329mm | 34mm  | Stainless Steel 304 | Brushed      |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**