

Fence Clamp, One Conductor

Power Utilities



FEATURES

Theft-deterrent appearance

Stainless steel hardware included

Tin plating minimizes the risk of corrosion

The clamp accepts the conductor either in parallel or at right angles to the pipe

SPECIFICATIONS


Table 1/1

Catalog Number	Fence Post Size, Nominal	Fence Post Outside Diameter, Actual (Ø)
FC073	1 1/2"	48 mm

ADDITIONAL PRODUCT DETAILS

IEC compliance is valid only for nVent ERICO Cu-Bond Conductors listed.

DIAGRAMS

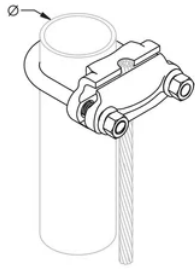

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE