


# Varistar Cable Ladder

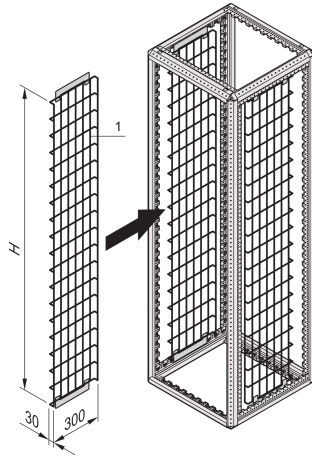

Vertical cable grid in different widths for Varistar free standing cabinets.

## CERTIFICATIONS



## FEATURES

Cables are assembled in place with cable ties or Velcro

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Panel

**Material:** Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Depth	Package Quantity	Finish
23130-554	38U	1800mm	300mm	300mm	2	Zinc Plated
23130-579	52U	2450mm	300mm		2	Zinc Plated

CatalogNumber	Rack Height	Height	Width	Depth	Package Quantity	Finish
23130-555	42U	2000mm	300mm	300mm	2	Zinc Plated

Table 2/2

Catalog Number	Type	Quick Ship
23130-554	Cable Ladder	No
23130-579	Vertical	No
23130-555	Cable Ladder	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**