

BC-MSM Conduit to Beam Clamp, Side Mount



CERTIFICATIONS



FEATURES

Easy installation to beam flanges

Eliminates offset bending conduit

Conduit clip rotates 360 degrees

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load	Certifications
EBC6MSM	172650	14 - 18 mm	16 mm Max	3 N·m	110N	
EBC812MSM	160180	18 - 30 mm	16 mm Max	3 N·m	110N	ITB
EBC16MSM	172660	23.4 - 35 mm	16 mm Max	3 N·m	110N	ITB

CatalogNumber	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load	Certifications
EBC20MSM	172670	35 - 42 mm	16 mm Max	3 N·m	110N	ITB
EBC24MSM	172680	42 - 50 mm	16 mm Max	3 N·m	110N	ITB
EBC32MSM	172690	50 - 60 mm	16 mm Max	3 N·m	110N	ITB

DIAGRAMS

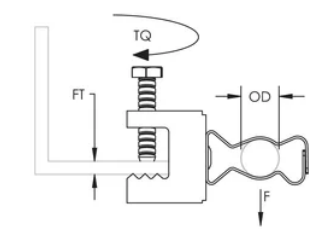

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

