


# Front Panel, Shielded, Side Hinged, 6 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

## CATALOG NUMBER

**20848-617**

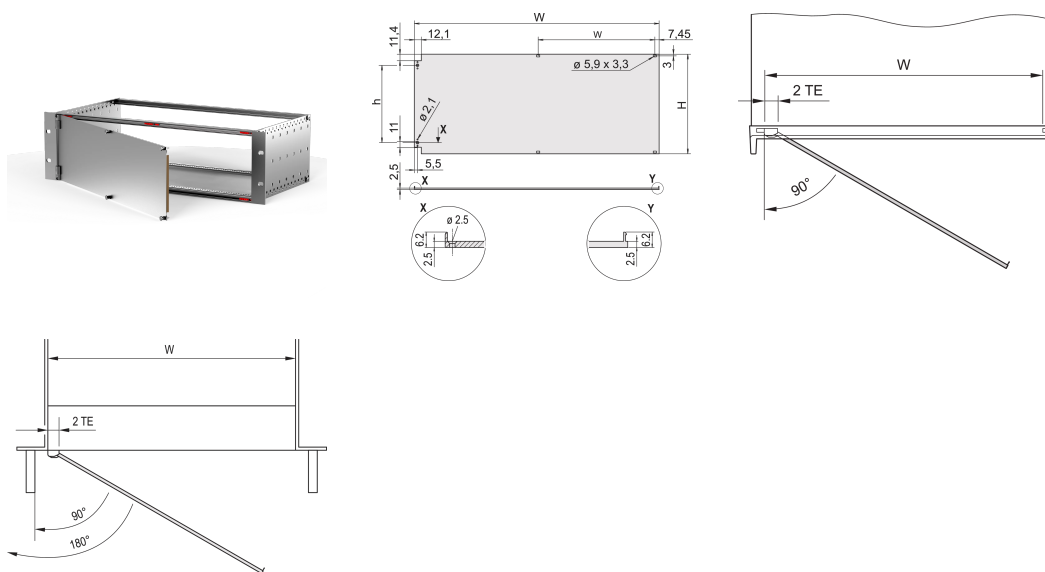

Front panel with textile EMC gasket, side hinged assembly.

## CERTIFICATIONS



## FEATURES

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails


Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUCT ATTRIBUTES

|                                   |
|-----------------------------------|
| Rack Height: 6U                   |
| Package Quantity: 1               |
| Accessory Type: Front panel       |
| Mounting: Hinged, Side            |
| Gasket Type: Textile EMC          |
| Front Finish: Anodized            |
| Rear Finish: Conductive           |
| Treated Edges: No                 |
| Depth (D): 2.5mm                  |
| EMC Shielding: No (Retrofittable) |
| Finish: Anodized; Passivated      |
| Height (H): 261.8mm               |
| Material: Aluminum                |
| Product Type: Front Panel         |
| Rack Width: 84HP                  |
| Type: Front Panel without Handle  |
| Width (W): 426.4mm                |
| Net Weight: 0.99kg                |

DIAGRAMS

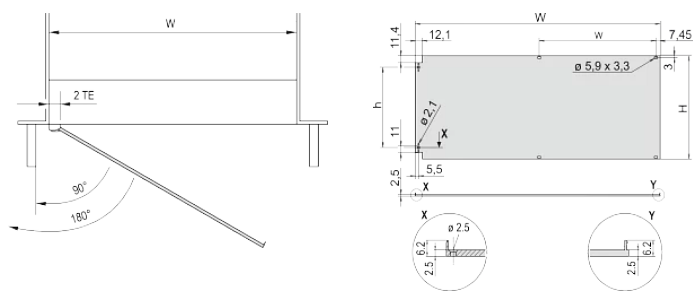

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**