


Plug-In Unit U-Profile Front Panel for Static Trapezoid Handle

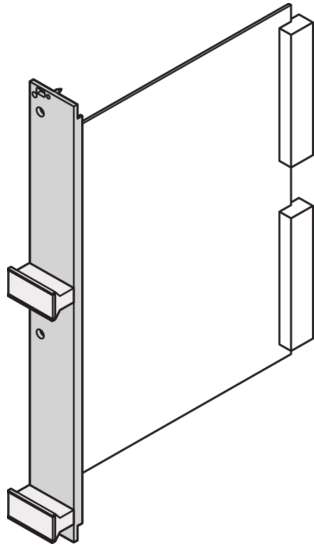

U-profile front panel. Enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel can be shielded with a textile gasket.

CERTIFICATIONS



FEATURES

Al extrusion, front anodized, rear conductive, alignment pin pressed-in, stainless steel

Front panel, U-profile, shieldable

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
30849-086	3U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-087	3U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-088	3U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-097	6U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-089	3U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-091	3U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-090	3U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-098	6U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-092	3U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-093	3U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-099	6U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
30849-100	6U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-101	6U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-102	6U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-103	6U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30849-104	6U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	Depth	Height	Width
30849-086	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	14.9mm
30849-087	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	20mm
30849-088	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	25mm
30849-097	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	14.9mm
30849-089	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	30.1mm
30849-091	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	40.3mm
30849-090	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	35.2mm
30849-098	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	20mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	Depth	Height	Width
30849-092	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	50.5mm
30849-093	Conductive	No	IEC 60297-3-101	2.5mm	128.4mm	60.6mm
30849-099	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	25mm
30849-100	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	30.1mm
30849-101	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	35.2mm
30849-102	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	40.3mm
30849-103	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	50.5mm
30849-104	Conductive	No	IEC 60297-3-101	2.5mm	261.8mm	60.6mm

Table 3/3	
Catalog Number	Quick Ship
30849-086	No
30849-087	No
30849-088	No
30849-097	No
30849-089	No
30849-091	No
30849-090	No
30849-098	No
30849-092	No

Catalog Number	Quick Ship
30849-093	No
30849-099	No
30849-100	No
30849-101	No
30849-102	No
30849-103	No
30849-104	No

ADDITIONAL PRODUCT DETAILS

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE