


Assembly Parts for Rugged Components

Power Utilities

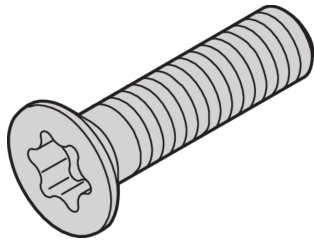

Assembly parts with thread-locking compound for rugged Side Panel, horizontal rail, cover plates, rear angle.

CERTIFICATIONS



FEATURES

Screws for the following fixings: Rugged side panel - horizontal rail, Rugged side panel - cover plate, Rugged side panel - rear angle

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Length	Package Quantity	Thread Size	Material	Product Family
24566-105	Countersunk Screw	7 mm	100	M4	Stainless Steel	EuropacPRO
24566-104	Panhead Screw	8 mm	100	M4	Stainless Steel	EuropacPRO
24566-103	Panhead Screw	10 mm	100	M4	Stainless Steel	EuropacPRO
24566-106	Countersunk Screw	10 mm	100	M4	Stainless Steel	EuropacPRO

CatalogNumber	Type	Length	Package Quantity	Thread Size	Material	Product Family
24566-101	Countersunk Screw	14 mm	100	M4	Stainless Steel	EuropacPRO
24566-102	Panhead Screw	14 mm	100	M4	Stainless Steel	EuropacPRO
24566-100	Countersunk Screw	18 mm	100	M4	Stainless Steel	EuropacPRO
24560-140	Square Nut		100		Stainless Steel	EuropacPRO

Table 2/2

Catalog Number	Product Type	Works With
24566-105	Assembly Kit	Subracks
24566-104	Assembly Kit	Subracks
24566-103	Assembly Kit	Subracks
24566-106	Assembly Kit	Subracks
24566-101	Assembly Kit	Subracks
24566-102	Assembly Kit	Subracks
24566-100	Assembly Kit	Subracks
24560-140	Assembly Kit	Subracks

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE