


# Novastar Raised Top Cover

## Power Utilities

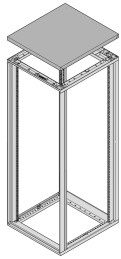

Raised top cover for better ventilation and heat escape.  
Novastar raised top cover is robust and not dismountable from the outside.

### CERTIFICATIONS



### FEATURES

Raised Top cover (31 mm) with all-round air gap of 10 mm

Top cover attached from the inside (no screws on the outside)

Suitable for placing heavy parts on the top cover

Incl. grounding

Robust version, load-carrying capacity 50 kg

### SPECIFICATIONS

Table 1/1

Catalog Number	Depth	Color	Color Code	Product Type	Type	Width
25230-039	500 mm	Black Grey	RAL 7021	Cabinet/Rack Top Cover	Raised	553 mm
25230-037	800 mm	Black Grey	RAL 7021	Cabinet/Rack Top Cover	Raised	553 mm

CatalogNumber	Depth	Color	Color Code	Product Type	Type	Width
25230-038	600 mm	Black Grey	RAL 7021	Cabinet/Rack Top Cover	Raised	553 mm
25230-141	900 mm	Black Grey	RAL 7021	Cabinet/Rack Top Cover	Raised	553 mm
25230-142	1000 mm	Black Grey	RAL 7021	Cabinet/Rack Top Cover	Raised	553 mm

## ADDITIONAL PRODUCT DETAILS

Please order lifting eye separately if required.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**