


Front Panel Kit, Unshielded, Bottom Hinged, 4 U, 84 HP, 2.5 mm, Al, Anodized

CATALOG NUMBER

20838-279

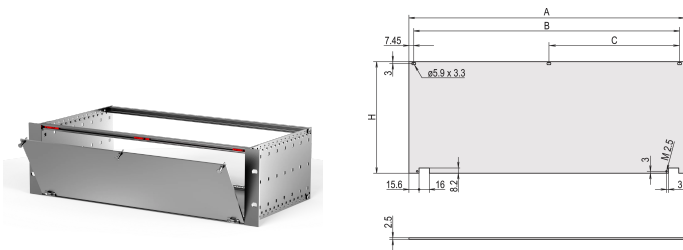

Unshielded front panel bottom hinged.

CERTIFICATIONS



FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

PRODUCT ATTRIBUTES

Rack Height: 4U

Accessory Type: Front panel

Rack Width: 84HP

Package Quantity: 1

Mounting: Hinged, Bottom

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Depth (D): 2.5mm

Finish: Anodized

Material: Aluminum

Type: Front Panel without Handle

Width (W): 426.4mm

Front panel can be removed in opened position ($> 135^\circ$).

Technical drawing of a rectangular plate with the following dimensions and tolerances:

- Overall width: A
- Overall height: H
- Top-left corner: $R7.45$
- Top-right corner: $R7.45$
- Bottom-left corner: $R15.6$
- Bottom-right corner: $R15.6$
- Top edge: B (left section), C (right section)
- Left edge: 15.6 (bottom section), 16.2 (top section)
- Right edge: 16.2 (bottom section), 15.6 (top section)
- Bottom edge: 15.6 (left section), 16.2 (right section)
- Internal dimensions: 15.6 (left), 16.2 (right), 15.6 (bottom), 16.2 (top)
- Internal features: $\phi 5.9 \times 3.3$ (top-left), $M2.5$ (bottom-right)
- Internal dimensions: 15.6 (left), 16.2 (right), 15.6 (bottom), 16.2 (top)

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Straubenhardt, Germany
 +49.7082.794.0
 Betschdorf, France
 +33.3.88.90.64.90
 Warsaw, Poland
 +48.22.209.98.35
 Assago, Italy
 +39.02.932.7141
 Chat with us:
nvent.com/schroff

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE