


# Plug-In Unit Kit With IEL Handle, Shielded, Black, 6 U

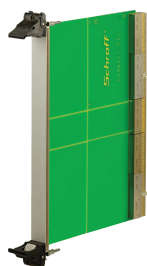

Plug-in unit, with IEL inserter/extractor black handle, 6 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

## CERTIFICATIONS



## FEATURES

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel with Handle (PIU)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	EMC Gasket Type	Front Finish
----------------	------------	------------------	-------------	----------	-----------------	--------------

20848-592	4HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-594	6HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-596	8HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-597	10HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-598	12HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized

Table 2/3


Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Rack Height
20848-592	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-594	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-596	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-597	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-598	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U

Table 3/3

Catalog Number	Width (W)	Quick Ship
----------------	-----------	------------

20848-592	20mm	No
20848-594	30.1mm	No
20848-596	40.3mm	No
20848-597	50.5mm	No
20848-598	60.6mm	No

### DIAGRAMS

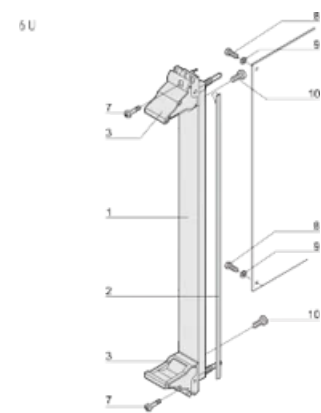

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, use, or modification of nVent products may void the warranty and create a safety hazard.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**