


# nVent CADDY Speed Link SLK with Threaded Stud End



## CERTIFICATIONS

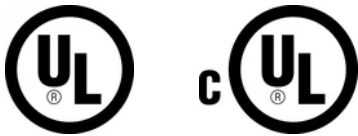

## FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polypropylene;Zinc Alloy
<b>Complies With:</b>	SMACNA HVAC-DCS


Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)
SLK2L3SEM8	196561	2 mm	3m	8	45mm	55 mm

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)
SLK2L5SEM8	196563	2 mm	5m	8	45mm	55 mm
SLK3L2SEM10	196718	3 mm	2m	10	45mm	62 mm
SLK3L3SEM10	196719	3 mm	3m	10	45mm	62 mm
SLK3L5SEM10	196720	3 mm	5m	10	45mm	62 mm

Table 2/2						
Catalog Number	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load	Certifications
SLK2L3SEM8	196561	19 mm	12.5 mm	90 ° Max	440N	UL, cUL
SLK2L5SEM8	196563	19 mm	12.5 mm	90 ° Max	440N	UL, cUL
SLK3L2SEM10	196718	24 mm	16 mm	90 ° Max	890N	
SLK3L3SEM10	196719	24 mm	16 mm	90 ° Max	890N	
SLK3L5SEM10	196720	24 mm	16 mm	90 ° Max	890N	

## DIAGRAMS

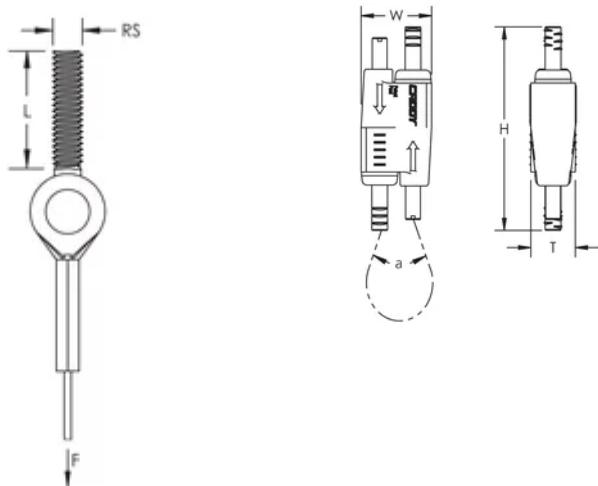

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

