

# USC Universal Strut Clamp for Pipe/Conduit



## FEATURES

Consists of two clamps, nut and bolt

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

## SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC026EG	712065	25.4 - 26.9 mm	20	32 mm	1.5 mm	2000N
USC022EG	712050	21.5 - 22.2 mm		32 mm	1.5 mm	2000N
USC033EG	712085	32.8 - 33.4 mm		32 mm	1.5 mm	2000N
USC040EG	712100	38.4 - 40.6 mm		32 mm	2 mm	2670N
USC048EG	712115	47.6 - 50 mm	40	32 mm	2 mm	2670N

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC060EG	712035	59.5 - 62.2 mm	50	32 mm	2.5 mm	3780N
USC063EG	712140	62.3 - 64.5 mm		32 mm	2.5 mm	3780N
USC073EG	712160	69.9 - 73 mm		32 mm	2.5 mm	3780N
USC086EG	712180	84.0 - 88.9 mm	80	32 mm	2.5 mm	3780N
USC101EG	712200	98.4 - 102.6 mm	90	32 mm	2.5 mm	3780N

## DIAGRAMS

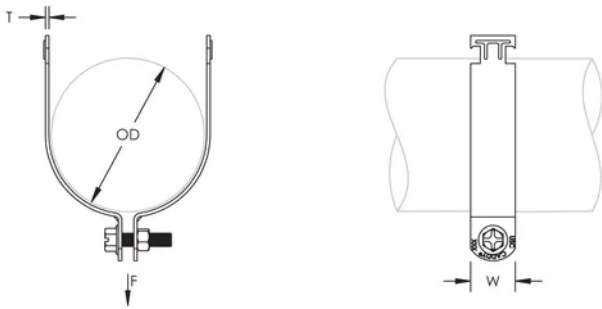

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

