


# WBT Performance Cable Tray Polymer Insert

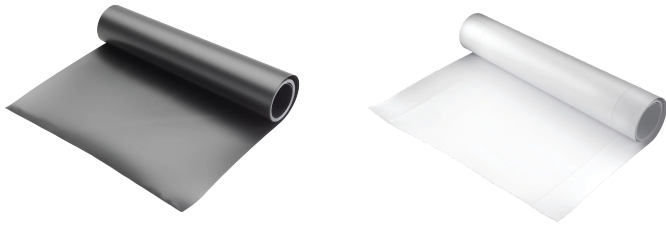

The nVent CADDY WBT Performance Cable Tray Polymer Insert utilizes a flame-retardant polymer to envelop the entire tray-providing bottom, side and cover protection. Available options include a flat bottom or a prescored version to the tray depth for coverage of the bottom and sides.

## FEATURES

Standard black finish for use with divider posts

Polymer insert rolls into the tray bottom

Multiple color options to coordinate with cable tray selection

## SPECIFICATIONS

**Material:** Polymer


Table 1/1

Catalog Number	Color	Height (H)	Width (W)	Length (L)	Unit Weight	Sides Included
WBTFORM04BA	Black		92.2 mm	3048mm	0.02 kg	No
WBTFORM06BA	Black		143 mm	3048mm	0.03 kg	No
WBTFORM08BA	Black		193.8 mm	3048mm	0.04 kg	No
WBTFORM2X4BA	Black	50.8 mm	92.2 mm	3048mm	0.04 kg	Yes

CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Unit Weight	Sides Included
WBTFORM2X6B A	Black	50.8 mm	143 mm	3048mm	0.05 kg	Yes
WBTFORM12BA	Black		295.4 mm	3048mm	0.06 kg	No
WBTFORM2X8B A	Black	50.8 mm	193.8 mm	3048mm	0.06 kg	Yes
WBTFORM4X4B A	Black	101.6 mm	92.2 mm	3048mm	0.06 kg	Yes
WBTFORM4X6B A	Black	101.6 mm	143 mm	3048mm	0.07 kg	Yes
WBTFORM16BA	Black		397 mm	3048mm	0.08 kg	No
WBTFORM2X12 BA	Black	50.8 mm	295.4 mm	3048mm	0.08 kg	Yes
WBTFORM4X8B A	Black	101.6 mm	193.8 mm	3048mm	0.08 kg	Yes
WBTFORM18BA	Black		447.8 mm	3048mm	0.09 kg	No
WBTFORM20BA	Black		498.6 mm	3048mm	0.1 kg	No
WBTFORM2X16 BA	Black	50.8 mm	397 mm	3048mm	0.1 kg	Yes
WBTFORM4X12 BA	Black	101.6 mm	295.4 mm	3048mm	0.1 kg	Yes
WBTFORM6X8B A	Black	152.4 mm	193.8 mm	3048mm	0.1 kg	Yes
WBTFORM2X18 BA	Black	50.8 mm	447.8 mm	3048mm	0.11 kg	Yes
WBTFORM24BA	Black		600.2 mm	3048mm	0.12 kg	No

CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Unit Weight	Sides Included
WBTFORM2X20 BA	Black	50.8 mm	498.6 mm	3048mm	0.12 kg	Yes
WBTFORM4X16 BA	Black	101.6 mm	397 mm	3048mm	0.12 kg	Yes
WBTFORM6X12 BA	Black	152.4 mm	295.4 mm	3048mm	0.12 kg	Yes
WBTFORM4X18 BA	Black	101.6 mm	447.8 mm	3048mm	0.13 kg	Yes
WBTFORM2X24 BA	Black	50.8 mm	600.2 mm	3048mm	0.14 kg	Yes
WBTFORM4X20 BA	Black	101.6 mm	498.6 mm	3048mm	0.14 kg	Yes
WBTFORM6X16 BA	Black	152.4 mm	397 mm	3048mm	0.14 kg	Yes
WBTFORM4X24 BA	Black	101.6 mm	600.2 mm	3048mm	0.16 kg	Yes
WBTFORM6X18 BA	Black	152.4 mm	447.8 mm	3048mm	0.16 kg	Yes
WBTFORM6X20 BA	Black	152.4 mm	498.6 mm	3048mm	0.18 kg	Yes
WBTFORM6X24 BA	Black	152.4 mm	600.2 mm	3048mm	0.18 kg	Yes

## DIAGRAMS

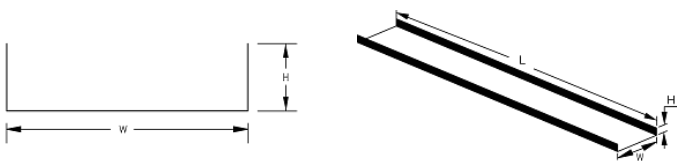

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

