


WBT Performance Cable Tray PreForm Tee

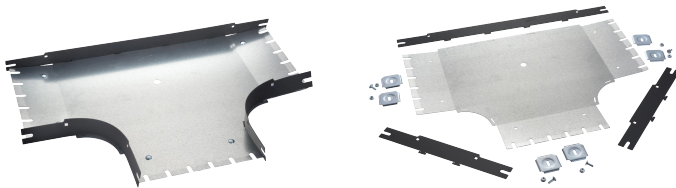

The nVent CADDY WBT Performance Cable Tray PreForm Tee is a precision-engineered solution designed to streamline cable tray installations when routing cabling in two or three different directions. With its pre-galvanized steel base and interlocking polymer sidewalls, the PreForm Tee delivers a clean, consistent, and tool-free installation experience.

Additionally, the PreForm Tee significantly reduces installation time by eliminating the need for field cutting or job site configuration. This translates into improved productivity and increased efficiency, especially in retrofit scenarios where flexibility is critical.

FEATURES

Multiple color options to coordinate with cable tray selection

Flame-retardant polymer rails ensure the safety of high-performance cabling

Routes cable systems in two or three directions

Provides a clean bend radius and helps to protect the natural bend radius of varying cable systems

SPECIFICATIONS

Finish: Pregalvanized;Polyurethane

Material: Steel

Table 1/2


Catalog Number	Color	Height (H)	Width (W)	Length (L)	Hole Size (HS)	Radius (R)
WBTT2X4		50.8 mm	317.5 mm	513.08mm		94.64mm
WBTT2X4BA	Black	50.8 mm	317.5 mm	513.08mm		94.64mm

CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Hole Size (HS)	Radius (R)
WBTT2X6BA	Black	50.8 mm	365.76 mm	561.34mm		94.64mm
WBTT2X6		50.8 mm	365.76 mm	561.34mm		94.64mm
WBTT2X18		50.8 mm	668.02 mm	863.6mm	19.05 mm	94.64mm
WBTT2X18BA	Black	50.8 mm	668.02 mm	863.6mm	19.05 mm	94.64mm
WBTT2X24		50.8 mm	817.88 mm	1013.46mm	19.05 mm	94.64mm
WBTT2X12BA	Black	50.8 mm	515.62 mm	711.2mm	19.05 mm	94.64mm
WBTT2X24BA	Black	50.8 mm	817.88 mm	1013.46mm	19.05 mm	94.64mm
WBTT2X12		50.8 mm	515.62 mm	711.2mm	19.05 mm	94.64mm

Table 2/2	
Catalog Number	Unit Weight
WBTT2X4	0.454 kg
WBTT2X4BA	0.454 kg
WBTT2X6BA	1.361 kg
WBTT2X6	1.361 kg
WBTT2X18	4.536 kg
WBTT2X18BA	4.536 kg
WBTT2X24	7.257 kg
WBTT2X12BA	2.722 kg
WBTT2X24BA	7.257 kg

Catalog Number	Unit Weight
WBTT2X12	2.722 kg

DIAGRAMS

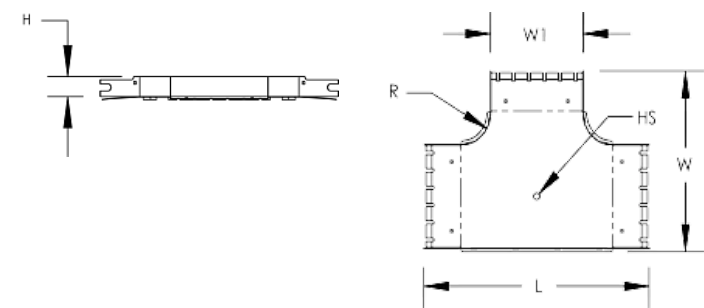

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

