


# Air Terminal Base, Ridge Mount, Imperial Thread



## CERTIFICATIONS

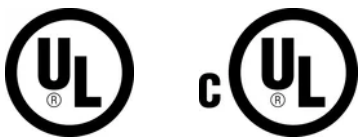

## FEATURES

For use on ridged roof

Can be easily formed to accommodate a variety of angles

Positive single bolt tension for multi-directional cable clamping

## SPECIFICATIONS

**Conductor Size, UL:** Class 1 - Class 2 (4/0 Max)

Table 1/2


Catalog Number	Material	Finish	Thread Size (TS)	Depth (D)	Height (H)	Width (W)
LPA34512	Aluminum		1/2" UNC	87.63mm	38.1 mm	260.35 mm
LPA34558	Aluminum		5/8" UNC	87.63mm	38.1 mm	260.35 mm

CatalogNumber	Material	Finish	Thread Size (TS)	Depth (D)	Height (H)	Width (W)
LPC34512	Copper		1/2" UNC	87.63mm	38.1 mm	260.35 mm
LPC34538	Copper		3/8" UNC	87.63mm	38.1 mm	260.35 mm
LPC34558	Copper		5/8" UNC	87.63mm	38.1 mm	260.35 mm
LPC345L12	Copper	Tinned	1/2" UNC	87.63mm	38.1 mm	260.35 mm
LPC345L38	Copper	Tinned	3/8" UNC	87.63mm	38.1 mm	260.35 mm
LPC345L58	Copper	Tinned	5/8" UNC	87.63mm	38.1 mm	260.35 mm

Table 2/2

Catalog Number	Hole Size (HS)	Unit Weight
LPA34512	6.6 mm	0.18 kg
LPA34558	6.6 mm	0.18 kg
LPC34512	6.6 mm	0.61 kg
LPC34538	6.6 mm	0.61 kg
LPC34558	6.6 mm	0.61 kg
LPC345L12	6.6 mm	0.61 kg
LPC345L38	6.6 mm	0.61 kg
LPC345L58	6.6 mm	0.61 kg

## DIAGRAMS

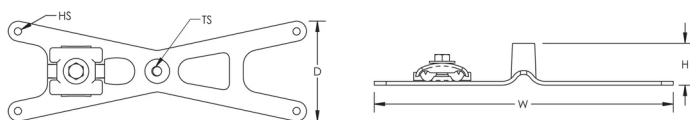

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**⚠ WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**